

Connectivity Solutions



Danfoss Connected Solutions



Connectivity and analytics that helps you profit from the power of data



Reduces the machine's scheduled downtime





Identification of best practices in productivity




User-intuitive and customizable portal

Asset connectivity solution PLUS+1[®] Connect

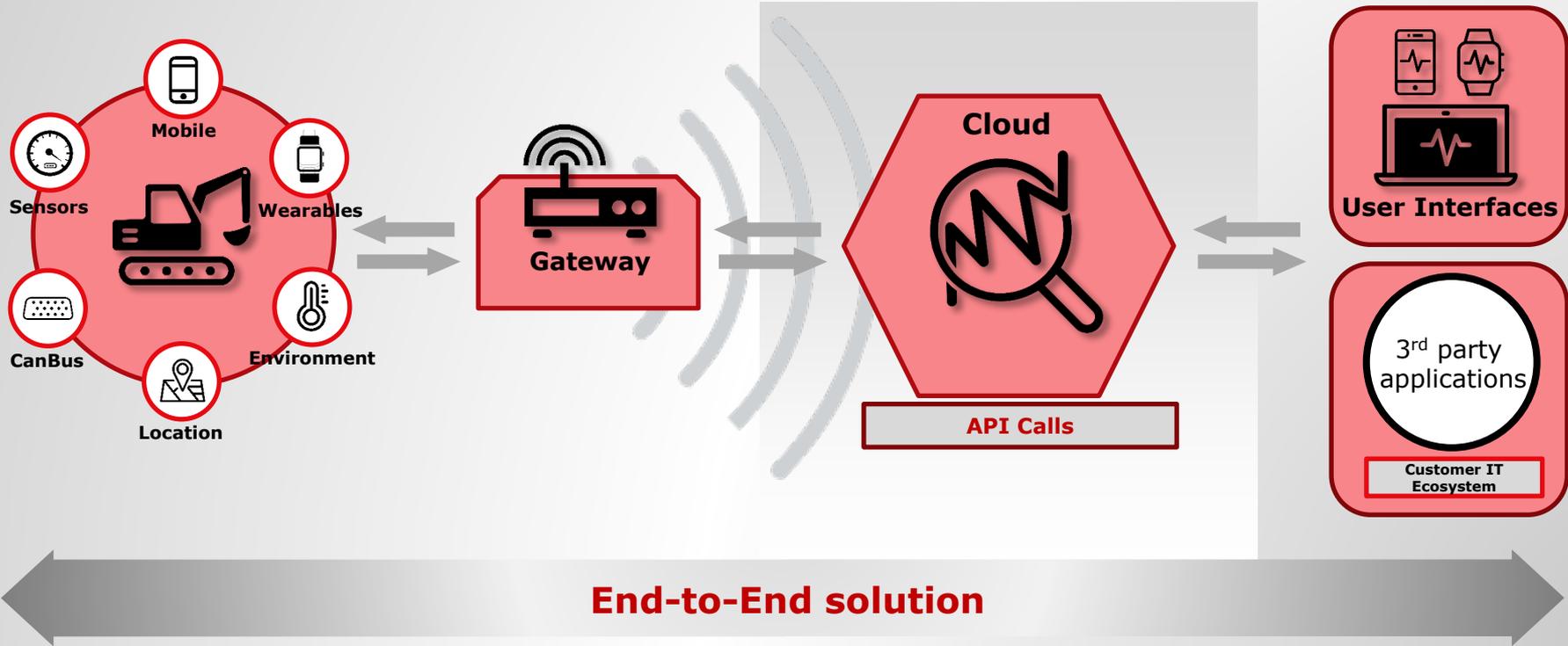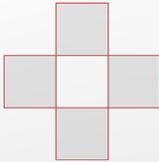

PLUS+1[®] Connect Services

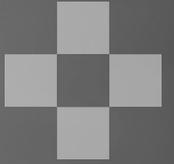

**Productivity
Optimization**




**Fleet
Management**



Reports



Geo-Fencing

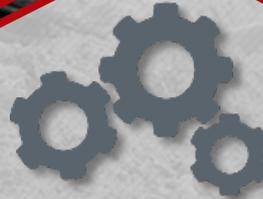


**Condition
Monitoring**



Alerts


Specifications of the CS100 IoT gateway

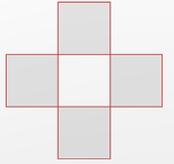

Connectivity	5G (LTE-M) 2G
Configurable / programmable	Configurable via PLUS+1® Connect portal
Operating system type	Embedded OS
Storage	16 MBytes
Operator ID	none
I/O	2 digital/analog in & outputs
Battery	None
Wakeup functions	Engine keyswitch internal timer




Specifications of the CS500 IoT gateway

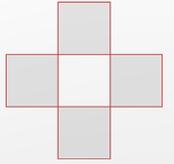

Connectivity	4G 3G 2G
Configurable / programmable	GUIDE programmable, Configurable via PLUS+1® Connect portal
Operating system type	Embedded OS
Storage	256 MBytes
Operator ID	none
I/O	2 digital or analog inputs 2 digital inputs 2 digital/analog in & outputs
Battery	none
Wakeup functions	Engine keyswitch Internal timer



Specifications of the CS10 IoT gateway

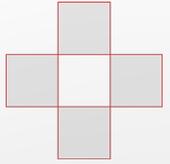

Connectivity	Wi-Fi Bluetooth classic Bluetooth low energy 4.2
Configurable / programmable	GUIDE programmable, configurable via mobile service tool
Operating system type	Linux
Storage	256 MBytes
Operator ID	none
I/O	1 digital input
Battery	none
Wakeup functions	Engine keyswitch

